




Narrow electronic circuit breakers

Universal at 6 mm

Narrow electronic circuit breakers

Ideally suited to simple, space-saving potential distribution: the PTCB single-channel electronic circuit breaker can be bridged to the CLIPLINE complete terminal block system and offers an adjustment range from 1 to 8 A with a narrow overall width.

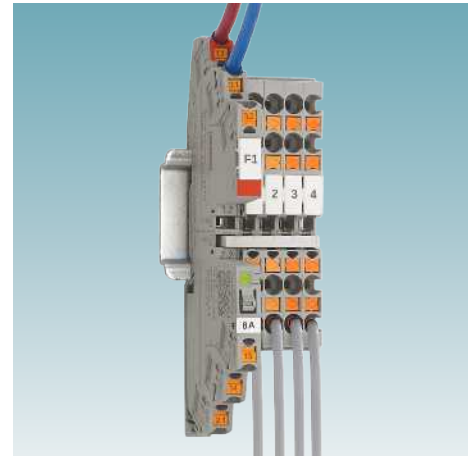



Further information and products regarding PTCB electronic circuit breakers: Simply enter the web code into the search field on our website.

i Web code: #1649

Your advantages

- ✓ Simple application setup with the capability of bridging to the CLIPLINE complete terminal block range
- ✓ More space in the control cabinet: narrow protection with a width of just 6 mm
- ✓ Flexible use and less inventory management due to adjustable current values on each device for a wide range of applications

Insight into our product range

				
Description	Device circuit breakers with adjustable nominal currents		Device circuit breakers with fixed nominal currents	
Nominal current	1 A ... 4 A	1 A ... 8 A	1 A	8 A
Operating voltage	18 V DC ... 27.5 V DC	18 V DC ... 30 V DC	18 V DC ... 30 V DC	18 V DC ... 30 V DC
Communication	Status output and reset input	Floating contact 13-14	Status output and reset input	Floating contact 13-14
NEC Class 2	✓		✓	
Type	PTCB E1 24DC/1-4A SI-R	PTCB E1 24DC/1-8A NO	PTCB E1 24DC/1A SI-R	PTCB E1 24DC/8A NO
Order No.	1135753	2908262	1135751	2909910

phoenixcontact.com